


AIRMAX

SYNTHETIC AIRFILTER MEDIA

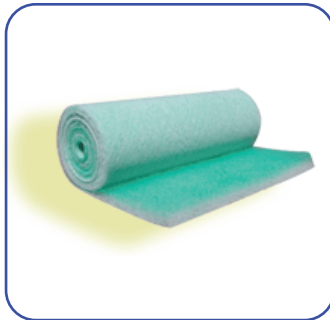


Ceiling fine filter

F5 (EU5)




Filtration Mats

For rough and fine filtration
G2 - G4 (EU2 - EU4)

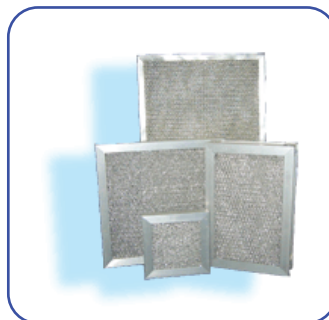

Aluminium Filter

Flat type
1", 2" and customs made

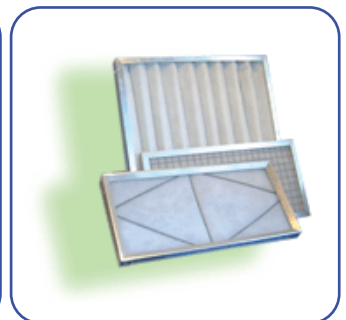

Extruded Frame

Flat & Pleated type
1", 2" and customs made

For AHU , First Stage Filter & Paint Spray Booth.
Available in all sizes.

Applications

- Electronics Air Cleaner
- Auto Air Conditioners
- Air Handling Unit
- Kichen hood
- Computer Room
- Department Store
- Office
- Hotel
- Hospital

Performance Data

TYPE		AM 150	AM 220	AM 290	AM 350	AM 400	AM 560G	Paintstop G2
Filter Classes	EN779	G2 (EU2)	G4 (EU4)	G4 (EU4)	G4 (EU4)	G4 (EU4)	F5 (EU5)	G2 (EU2)
Average arrestance	%	65-80	> 90	> 90	> 90	> 90	97	93-97
Nominal air flow rate	CMH	5400	5400	5400	5400	5400	900	2500-6300
Initial pressure drop	Pa/m ²	25	35	52	50	60	25	7
Recommend final pressure	Pa/m ²	250	250	250	250	250	450	150
Media thickness	mm.	10	18	20	20	22	25	50
Surface weight approx.	g/m ²	150	220	290	280	350	550	50
Media color		white	white	Blue/white	white	white	white	Green/white
Flame resistance	DIN 53438	F1	F1	F1	F1	F1	F1	180 °C
Roll size	m.	2 x 20	2 x 20	2 x 20	2 x 20	2 x 20	2 x 20	1.5 x 20

AIRMAX reserves our right to change design and specifications without notice.